


規格：

型號	MVFA-230	MVFA-231	MVFA-240
配管口徑代號	8A		
配管口徑尺寸	Rc1/4		
方口數	3口		4口
位置數	2位置		
使用流體	空氣		
使用壓力範圍	0~0.7 MPa		
耐壓力	1 MPa		
有效斷面積	8 mm ²		
周圍溫度	-5~+60°C (不凍結)		
重量(※)	684 (1426) g	739 (1481) g	774 (1516) g

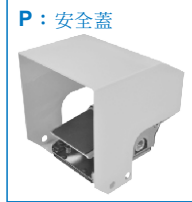

訂購代號：

MVFA - 230 - 8A - P L - G

型號

8A : Rc1/4

P : 安全蓋
L : 鎖定機構

配管口螺牙
無 : Rc牙
G : G牙
NPT : NPT牙

230 : 3口2位常閉型
231 : 3口2位常開型
240 : 4口2位

MVFA-230-8A-(L)

 
MVFA-231-8A-(L)

MVFA-230-8A-P(L)


MVFA-231-8A-P(L)

MVFA-230 / 231








N.C.





N.O.

 

MVFA-240

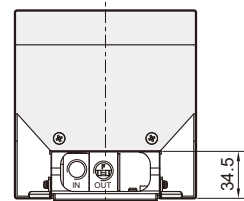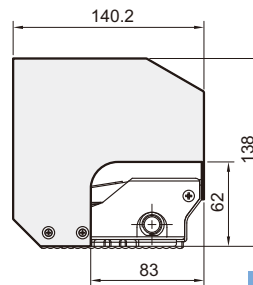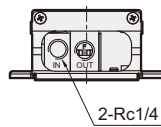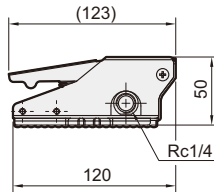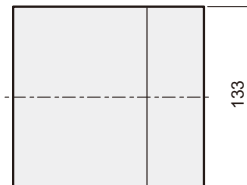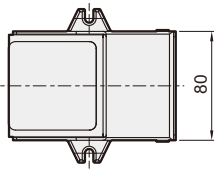 

MVFA-240-8A-(L)

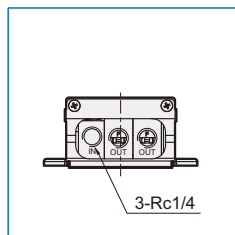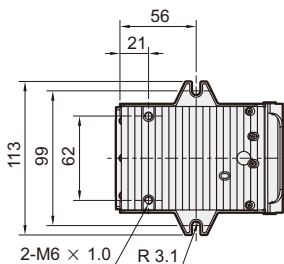

MVFA-240-8A-P(L)

