

# MAFR200 series

AIR UNIT (F.R.UNIT)

 


mindman



MAFR200L

### Symbol




### Specification

Model	MAFR200	
Bore No.	6A	8A
Port size	1/8	1/4
Medium	Air	
Operating pressure range	By order specifications	
Proof pressure	1.5 MPa	
Regulated pressure range	0.05~0.85 MPa	
Ambient temperature	-5~+60°C (No freezing)	
Filter element	Standard: 40 μm, Option: 5 μm	
Attachment	Pressure gauge (PG-40), bracket	
Weight	257 g, 226 g (MAFR200L)	

※ Standard unit contains semi-auto-drain function when operating pressure below 0.05 MPa.

### Order example

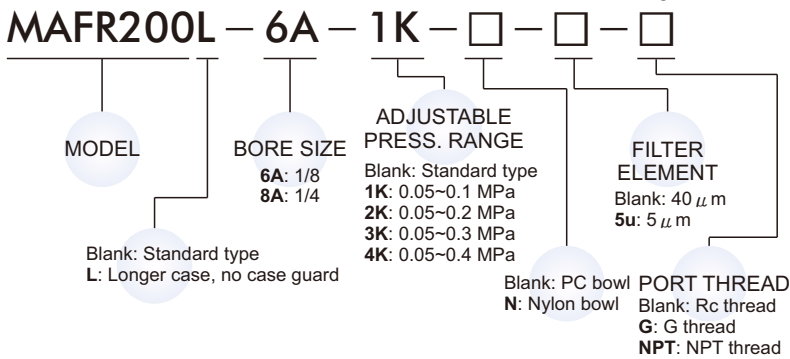

### Flow feature

